

# LC BODY WITH M24X1 THREAD

The new **M24X1 LC Body** will allow for customers to easily add quick disconnect functionality to M24 female threads. This thread is commonly found in metric plumbing and faucets.

**APPLICATIONS:** General Purpose, Plumbing

## KEY FEATURES:

- **Male M24X1 Thread:** Thread type is commonly found on European faucets
- **Brass Material:** Durable construction withstands high pressures and temperatures
- **Compatibility:** This LC body is compatible with LC, PLC and PLC12 series inserts
- **Chrome Plating:** Attractive Appearance

**AVAILABLE  
NOW!**



**Part Number: LC10M24**

**Part Number: LC10M24<sup>1</sup>**

## SPECIFICATIONS:

**Pressure:** Vacuum to 250psi


**Temperature:** -40°F to 180 °F (-40 °C to 82°C)

**Flow:** 2.8 Cv (mated with LC22006)


## MATERIALS:

**Main body components:** Chrome plated brass

**Springs:** Stainless Steel

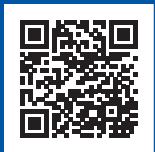

[CPCWORLDWIDE.COM /LC](http://CPCWORLDWIDE.COM/LC)

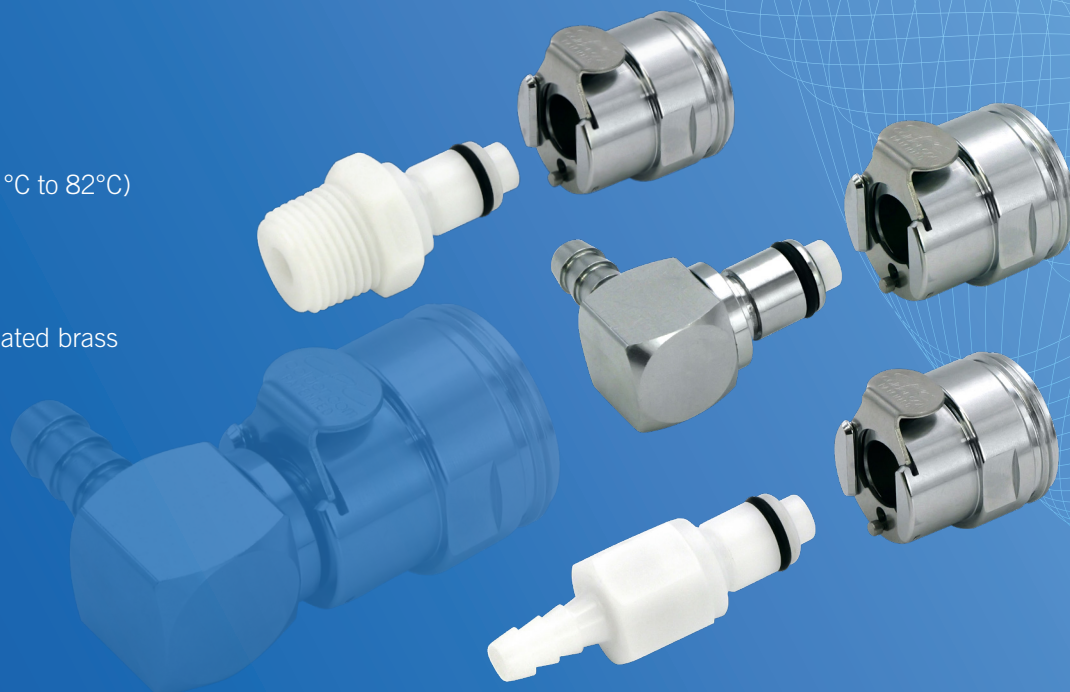

**WARRANTY:** All sales are subject to Colder Products Company's limited express warranty set forth in the CPC catalog. Visit [cpcworldwide.com/warranty](http://cpcworldwide.com/warranty) for more information.

**WARNING:** Due to the wide variety of possible fluid media and operating conditions, unintended consequences may result from the use of this product, all of which are beyond the control of CPC. It is the user's responsibility to carefully determine and test for compatibility for use within their application. All such risks shall be assumed by the buyer.

© 2025 BY COLDER PRODUCTS COMPANY. CPC, Colder Products Company, and Colder Products are registered trademarks with the United States Patent and Trademark Office. For detailed trademark information, please visit: [cpcworldwide.com/trademarks](http://cpcworldwide.com/trademarks).

